


## Flat magnet with internal thread, Neodymium, Ø: 6mm

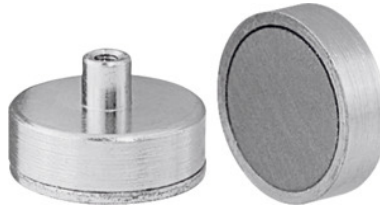

### Order data

Order number	085924 6
GTIN	2050001737717
Item class	08Q

### Description

#### Version:

- Temperature-resistant up to maximum 80 °C.
- Galvanised surface, magnetic core made of neodymium.
- Shielded flat magnet with 3 to 6 times the clamping force compared to hard ferrite magnets.

#### Application:

For clamping, assembling, incorporation by pressing in, gluing or encapsulating.

#### Note:

Screw-in hooks with external thread under No. 085921.

### Technical description

Ø	6 mm
Height	4.5 mm
Height with thread	11.5 mm
Weight	2.7 g
Material of the surface	galvanised
maximum temperature resistance	80 °C
Threaded socket	yes
Nominal clamping force	5 N

Thread	M3 mm
Material of the magnet core	Neodymium
Type of product	Flat gripper magnet

---

## Accessories

Screw-in hook set with external thread 10 pieces Thread M3	085921 M3
--	-----------