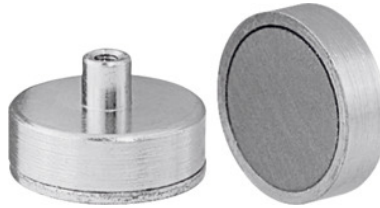


Flat magnet with internal thread, SmCo₅, Ø: 32mm**Order data**

Order number	085922 32
GTIN	2050000965258
Item class	08Q

Description**Version:**

- Temperature-resistant up to maximum 200 °C.
- Galvanised surface, magnetic core made of samarium-cobalt (SmCo₅).
- Shielded flat magnet with 3 to 6 times the clamping force compared to hard ferrite magnets.

Application:

For clamping, assembling, incorporation by pressing in, gluing or encapsulating.

Note:

Screw-in hooks with external thread under No. 085921.

Technical description

Height	7 mm
Nominal clamping force	220 N
Material of the surface	galvanised
Height with thread	15.5 mm
Weight	48 g
Threaded socket	yes
Ø	32 mm
maximum temperature resistance	200 °C

Thread	M5 mm
Material of the magnet core	SmCo ₅
Type of product	Flat gripper magnet

Accessories

Screw-in hook set with external thread10 pieces Thread M5	085921 M5
---	-----------