


Flat magnet without thread, Neodymium, Ø: 6mm

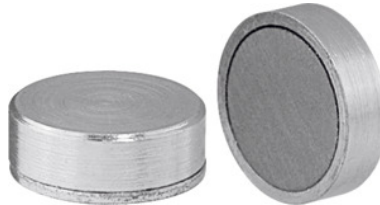

Order data

Order number	085923 6
GTIN	2050001735768
Item class	08Q

Description

Version:

- Temperature-resistant up to maximum 80 °C.
- Galvanised surface, magnetic core made of neodymium.
- Shielded flat magnet with 3 to 6 times the clamping force compared to hard ferrite magnets.

Application:

For clamping, assembling, incorporation by pressing in, gluing or encapsulating.

Technical description

Nominal clamping force	5 N
Height	4.5 mm
Material of the surface	galvanised
maximum temperature resistance	80 °C
Ø	6 mm
Weight	1 g
Material of the magnet core	Neodymium
Type of product	Flat gripper magnet

