


## Flat magnet without thread, Neodymium, Ø: 8mm

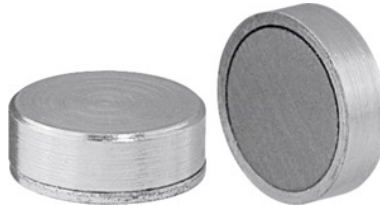

### Order data

Order number	085923 8
GTIN	2050001737557
Item class	08Q

### Description

#### Version:

- Temperature-resistant up to maximum 80 °C.
- Galvanised surface, magnetic core made of neodymium.
- Shielded flat magnet with 3 to 6 times the clamping force compared to hard ferrite magnets.

#### Application:

For clamping, assembling, incorporation by pressing in, gluing or encapsulating.

### Technical description

maximum temperature resistance	80 °C
Material of the surface	galvanised
Nominal clamping force	13 N
Weight	1.8 g
Height	4.5 mm
Ø	8 mm
Material of the magnet core	Neodymium
Type of product	Flat gripper magnet

