


## Flat magnet without thread, Neodymium, Ø: 10mm

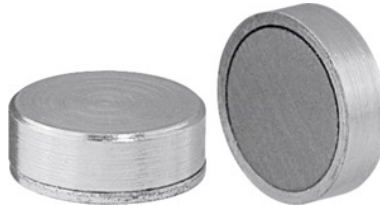

### Order data

Order number	085923 10
GTIN	2050001737564
Item class	08Q

### Description

#### Version:

- Temperature-resistant up to maximum 80 °C.
- Galvanised surface, magnetic core made of neodymium.
- Shielded flat magnet with 3 to 6 times the clamping force compared to hard ferrite magnets.

#### Application:

For clamping, assembling, incorporation by pressing in, gluing or encapsulating.

### Technical description

Ø	10 mm
maximum temperature resistance	80 °C
Height	4.5 mm
Weight	2.5 g
Material of the surface	galvanised
Nominal clamping force	25 N
Material of the magnet core	Neodymium
Type of product	Flat gripper magnet

