


Flat magnet with internal thread, SmCo₅, Ø: 10mm

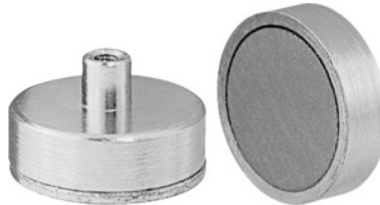

Order data

Order number	085922 10
GTIN	2050000964954
Item class	08Q

Description

Version:

- Temperature-resistant up to maximum 200 °C.
- Galvanised surface, magnetic core made of samarium-cobalt (SmCo₅).
- Shielded flat magnet with 3 to 6 times the clamping force compared to hard ferrite magnets.

Application:

For clamping, assembling, incorporation by pressing in, gluing or encapsulating.

Note:

Screw-in hooks with external thread under No. 085921.

Technical description

Height	4.5 mm
Nominal clamping force	20 N
maximum temperature resistance	200 °C
Threaded socket	yes
Weight	4.5 g
Ø	10 mm
Thread	M3 mm
Height with thread	11.5 mm

Material of the surface	galvanised
Material of the magnet core	SmCo ₅
Type of product	Flat gripper magnet

Accessories

Screw-in hook set with external thread 10 pieces Thread M3	085921 M3
--	-----------