


Flat magnet without thread, Neodymium, Ø: 16mm

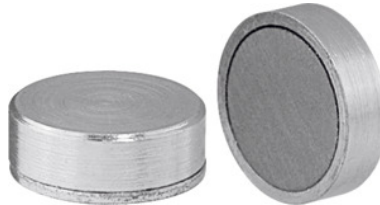

Order data

Order number	085923 16
GTIN	2050001735782
Item class	08Q

Description

Version:

- Temperature-resistant up to maximum 80 °C.
- Galvanised surface, magnetic core made of neodymium.
- Shielded flat magnet with 3 to 6 times the clamping force compared to hard ferrite magnets.

Application:

For clamping, assembling, incorporation by pressing in, gluing or encapsulating.

Technical description

Height	4.5 mm
Ø	16 mm
maximum temperature resistance	80 °C
Nominal clamping force	95 N
Weight	5.5 g
Material of the surface	galvanised
Material of the magnet core	Neodymium
Type of product	Flat gripper magnet

