


Flat magnet with internal thread, SmCo₅, Ø: 16mm

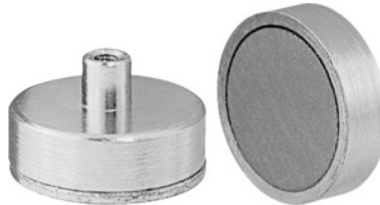

Order data

Order number	085922 16
GTIN	2050000964978
Item class	08Q

Description

Version:

- Temperature-resistant up to maximum 200 °C.
- Galvanised surface, magnetic core made of samarium-cobalt (SmCo₅).
- Shielded flat magnet with 3 to 6 times the clamping force compared to hard ferrite magnets.

Application:

For clamping, assembling, incorporation by pressing in, gluing or encapsulating.

Note:

Screw-in hooks with external thread under No. 085921.

Technical description

Threaded socket	yes
Ø	16 mm
maximum temperature resistance	200 °C
Height with thread	11.5 mm
Height	4.5 mm
Material of the surface	galvanised
Weight	9 g
Nominal clamping force	60 N

Thread	M4 mm
Material of the magnet core	SmCo ₅
Type of product	Flat gripper magnet

Accessories

Screw-in hook set with external thread 10 pieces Thread M4	085921 M4
--	-----------