


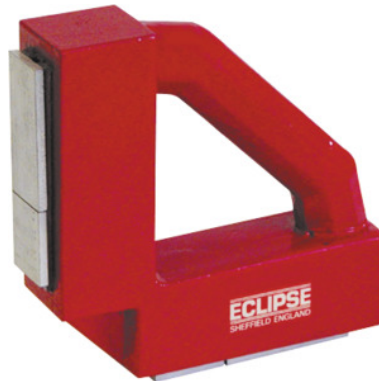

Magnetic clamp with 90° (fixed), Ferrite, Type: 971



Order data

| | |
|--------------|---------------|
| Order number | 085954 971 |
| GTIN | 2050000965494 |
| Item class | 08Q |

Description

Version:

Angular tolerance $\pm 0.05 / 100$ mm.

Application:

For clamping components at a fixed angle of 90° and for preparing welding and assembly operations.

Technical description

| | |
|--------------------------|------------|
| Height | 140 mm |
| Weight | 1.4 kg |
| Width | 35 mm |
| Type | 971 |
| Length | 140 mm |
| Angular adjustment range | 90 degrees |
| Nominal clamping force | 400 N |

| | |
|-----------------------------|--------------------|
| Material of the magnet core | Ferrite |
| Type of product | Magnet with switch |