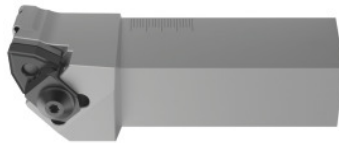


**Garant**
**GARANT Master eco clamping toolholder short, left-hand, Shank / insert size: 25/08mm**

**Order data**

|              |               |
|--------------|---------------|
| Order number | 251923 25/08  |
| GTIN         | 4062406734695 |
| Item class   | 21U           |

**Description**
**Version:**

Highly efficient cooling directly on the cutter and additional flank face cooling.

**Note:**

Coolant transfer via slot on the underside of the shank in conjunction with GARANT Master eco toolholders No. 319006 – 319136 or No. 317900 for shank length < 125 mm. Optional connection possibility via hose connection (G 1/8 inch) No. 269207 and 269208.

**Technical description**

|                            |                  |
|----------------------------|------------------|
| suitable indexable insert  | WN.. 0804..      |
| Clamping claw              | 259038 18        |
| Head length L <sub>1</sub> | 35 mm            |
| Screw for clamping claw    | 259021 6         |
| Shank size                 | 25 mm            |
| ISO code toolholder        | MWLNLR/L 2525X08 |
| Overall length L           | 105 mm           |
| Insert size                | 8 mm             |
| Pin                        | 259049 7         |

|                                 |                               |
|---------------------------------|-------------------------------|
| Series                          | Master Eco                    |
| Shim                            | 259033 6                      |
| Functional width L <sub>4</sub> | 32 mm                         |
| Standard                        | Works standard                |
| Application type                | left-hand                     |
| Through-coolant                 | yes                           |
| Setting angle $\kappa$          | 95 degrees                    |
| Application                     | External longitudinal turning |
| Application                     | External longitudinal turning |
| Type of product                 | QuickTurn clamping toolholder |