


SWISS TOOLS

Screw-on toolholder right-hand, HSK-T, Shank Ø / insert size: 40/16HPmm

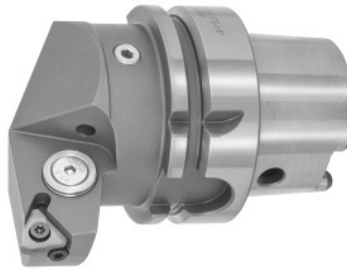

Order data

Order number	320105 40/16HP
GTIN	2050002062931
Item class	36D

Description

Note:

Order the suitable **HP nozzle** No. 320001 separately. Spare parts No.320610 – 320626 can be found in the spare parts list.

PSC clamping stud on request.

Technical description

suitable indexable insert	16E..
Insert size	16HP
Overhang dimension A	55 mm
Axis tip distance f	27 mm
Shank Ø	40 mm
Adapter	HSK-T
Application type	right-hand
Arbor standard	ISO 12164-3
Through-coolant	yes
Shank type	Hollow shank taper

Type of product

Boring bar