


SWISS TOOLS

Screw-on toolholder right-hand, HSK-T, Shank \varnothing / insert size: 40/16HPmm

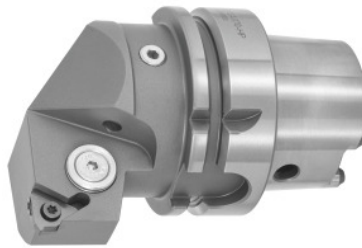

Order data

Order number	320115 40/16HP
GTIN	2050002062979
Item class	36D

Description

Note:

Order the suitable **HP nozzle** No. 320001 separately. Spare parts No.320610 – 320626 can be found in the spare parts list.

PSC clamping stud on request.

Technical description

Overhang dimension A	55 mm
Shank \varnothing	40 mm
Axis tip distance f	27 mm
Insert size	16HP
suitable indexable insert	16E..
Adapter	HSK-T
Application type	right-hand
Arbor standard	ISO 12164-3
Through-coolant	yes
Shank type	Hollow shank taper

Type of product

Boring bar