


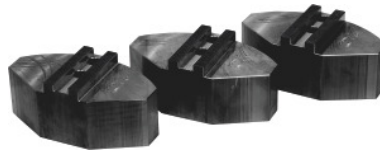

Segment jaws set, 3 pieces, Steel, for chuck type: 210



Order data

Order number	313738 210
GTIN	4060576180250
Item class	33T

Description

Version:

Precision milled slots and **precision ground** serrations, **burnished**.

Application:

All-round low-distortion clamping.

Material:

Quality product made of 16MnCr5.

Suitable for:

Heavy-duty chucks from Schunk, Röhmm and other heavy-duty chuck manufacturers.

Optional extras:

T-nuts No. 313505 – 313605.

Note:

- **When fitting to a chuck, please check serrations, slot width (D), and hole spacing (a, b).**
- **Aluminium top jaws on request.**

Technical description

Width B	140 mm
Bore spacing b	25 mm
for chuck type	210 mm
Height H	80 mm
Length L	70 mm
Slot width D	14 mm

Hole centre spacing a	30 mm
suitable for colour code	Schunk heavy-duty chucks and jaws
Type of product	Heavy-duty lathe chuck jaws