


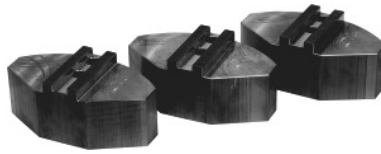

Segment jaws set, 3 pieces, Steel, for chuck type: 250



Order data

Order number	313738 250
GTIN	4060576180243
Item class	33T

Description

Version:

Precision milled slots and **precision ground** serrations, **burnished**.

Application:

All-round low-distortion clamping.

Material:

Quality product made of 16MnCr5.

Suitable for:

Heavy-duty chucks from Schunk, Röhm and other heavy-duty chuck manufacturers.

Optional extras:

T-nuts No. 313505 – 313605.

Note:

- **When fitting to a chuck, please check serrations, slot width (D), and hole spacing (a, b).**
- **Aluminium top jaws on request.**

Technical description

Height H	80 mm
Slot width D	16 mm
Width B	180 mm
Length L	80 mm
Bore spacing b	30 mm
Hole centre spacing a	30 mm

for chuck type	250 mm
suitable for colour code	Schunk heavy-duty chucks and jaws
Type of product	Heavy-duty lathe chuck jaws