




## TMSERROR, Type: C-MULTI

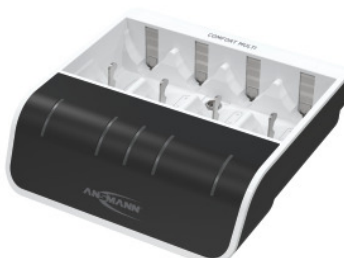

### Order data

Order number	081590 C-MULTI
GTIN	4013674161126
Item class	08C

### Description

#### Version:

Microprocessor-controlled charging and servicing stations for battery cells with **individual channel monitoring** and battery fault detection. Status display for each charging slot, automatic charging switch-off, overload protection and **trickle charging**. Input voltage 100–240 V. With intelligent "PERFECT 7" charging technology (rapid capacity test, gentle pre-charging, battery analysis, rapid charge, IQ shutdown, top-off charging, trickle charging) and 3-colour LED display for reading the cell status.

#### Application:

**NiMH battery charging points:** 1 – 4 × Micro AAA / Mignon AA / Baby C / Mono D and 1 × 9V block.

#### Attention:

German version. Order free UK adapter plug No. 08 1172\_GB

### Technical description

suitable battery - supplier / battery type / voltage	Type CAS 18 V
Length	151.8 mm
maximum charging current	0.8 A
Mains frequency	50 Hz

Height	149.6 mm
Nominal voltage	100 - 240 V
Width	47 mm
Maximum number of charging points	5
Interface	Digimatic interface
Type of product	Battery charger