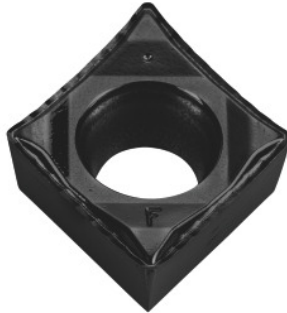


Garant
CC.T 060202, Grade: HB7315-1


Order data

Order number	260050 HB7315-1
GTIN	4062406769291
Item class	21G

Description

CCMT 060202 HB7315-1 Grade: HB7315-1
 Chip breaker: AF
 Tolerance: G
 Cutting depth a_p : 0.05 - 0.5 mm
 Feed f : 0.03 - 0.1 mm/rev.
 Cutting speed v_c main application: 120 - 600 m/min

Technical description

Chip breaker	AF
Tool material	Carbide
Cutting speed v_c main application	120 - 600 m/min
Cutting depth a_p	0.05 - 0.5 mm
Main application	N
Cutting conditions	continuous

Number of changes/inserts	2
Tolerance	G
Corner radius	0.2 mm
Finishing/roughing assignment	Finishing
ISO code indexable insert	CCGT 060202
Feed f	0.03 - 0.1 mm/rev.
Grade	HB7315-1
Type of product	Indexable insert for turning