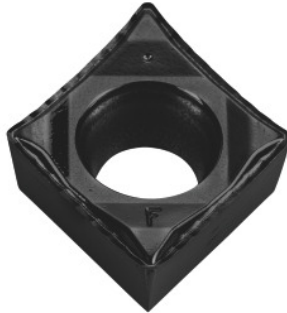


Garant
CC.T 060204, Grade: HB7315-1


Order data

Order number	260052 HB7315-1
GTIN	4062406769307
Item class	21G

Description

CC.T 060204 HB7315-1 Grade: HB7315-1
 Chip breaker: AF
 Tolerance: G
 Cutting depth a_p : 0.05 - 0.5 mm
 Feed f : 0.03 - 0.1 mm/rev.
 Cutting speed v_c main application: 120 - 600 m/min

Technical description

Cutting depth a_p	0.05 - 0.5 mm
Cutting conditions	continuous
Corner radius	0.4 mm
Finishing/roughing assignment	Finishing
Main application	N
Chip breaker	AF
Feed f	0.03 - 0.1 mm/rev.

Number of changes/inserts	2
Cutting speed v_c main application	120 - 600 m/min
Tolerance	G
Grade	HB7315-1
Tool material	Carbide
ISO code indexable insert	CCGT 060204
Type of product	Indexable insert for turning