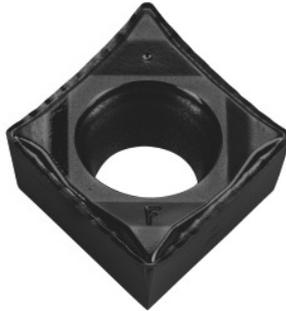


Garant**CC.T 120404, Grade: HB7315-1**

Order data

Order number	260064 HB7315-1
GTIN	4062406769949
Item class	21G

Description

CC.T 120404 HB7315-1 Grade: HB7315-1
Chip breaker: AF
Tolerance: G
Cutting depth a_p : 0.05 - 0.5 mm
Feed f : 0.03 - 0.1 mm/rev.
Cutting speed v_c main application: 120 - 600 m/min

Technical description

Tolerance	G
Tool material	Carbide
Finishing/roughing assignment	Finishing
Main application	N
Corner radius	0.4 mm
Cutting depth a_p	0.05 - 0.5 mm
Grade	HB7315-1

Cutting speed v_c main application	120 - 600 m/min
ISO code indexable insert	CCGT 120404
Chip breaker	AF
Cutting conditions	continuous
Number of changes/inserts	2
Feed f	0.03 - 0.1 mm/rev.
Type of product	Indexable insert for turning