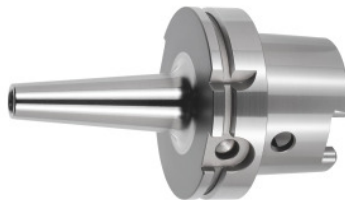


**Garant**

**Shrink-fit chuck, slim, long 4°30', HSK-A 100 A = 120, Clamping range Ø D1: 12mm**


**Order data**

Order number	308339 12
GTIN	4062406787103
Item class	31A

**Description**
**Version:**

- External taper 4°30'.
- With RFID/Balluffchip bore.
- HSK mating faces machined.

**Application:**

- For working in places where access is difficult.
- For clamping tools with parallel shank to h6 tolerance.

**Optional extras:**

Coolant pipe No. 309880, Plug-in socket No. 309890, Shrink-fit extension No. 302410 size 12/3 and 12/4. Shrink-fitting units No. 354210 – 354450.

**Technical description**

Overhang dimension A	120 mm
Clamping Ø D <sub>1</sub>	12 mm
External Ø D	33 mm
Ø D <sub>2</sub>	18 mm
Adapter	HSK-A 100 A = 120
Arbor standard	DIN 69893

Arbor standard	ISO 12164-1
Shape	A
Balance quality G at rotational speed	G 2.5 at 25,000 rpm
Concentricity	$\leq 3 \mu\text{m}$
Machining strategy	HSC
Type of product	Shrink-fit chuck