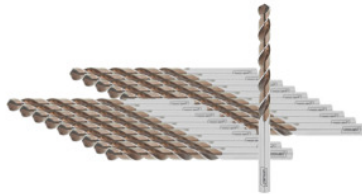


**HOLEX CleverDrill HSS jobber drill N, uncoated, Ø DC h8: 7mm****Order data**

Order number	GG4031 7
GTIN	4067263101864
Item class	GGN

Description**Version:**

HOLEX CleverDrill: Sturdy drill for all standard applications. Improved spot drilling behaviour due to cross-ground form. Standard core thickness and core taper. Profile ground. Surface: Bronze-coloured tempered helical flutes.

Same as No. 114031.

Recommendation:**Maximum drilling depth:**

$$L_2 = L_C - 1.5 \times D_C$$

Note:

Successor product to No. 114030.

Size 13.5 – 16: With stepped shank Ø 12.7 mm.

Technical description

Overall length L	109 mm
Number of cutting edges Z	2
Shank Ø D _s	7 mm
recommended maximum drilling depth L ₂	58.5 mm
Shank	Plain shank
Point angle	118 degrees

Flute length L_c	69 mm
Feed f in steel $< 750 \text{ N/mm}^2$	0.07 mm/rev.
Tolerance nominal \varnothing	h8
Standard	DIN 338
Nominal $\varnothing D_c$	7 mm
Contents	20
Series	CleverDrill
Coating	uncoated
Tool material	HSS
Type	N
Through-coolant	no
Colour ring	without
Type of product	Jobber drill

User data

	Suitability	V_c	ISO code
Alu plastics	suitable only under restricted conditions	80 m/min	N
Aluminium (short chipping)	suitable only under restricted conditions	60 m/min	N
Alu $> 10\% \text{ Si}$	suitable only under restricted conditions	50 m/min	N
Steel $< 500 \text{ N/mm}^2$	suitable	35 m/min	P
Steel $< 750 \text{ N/mm}^2$	suitable	32 m/min	P
Steel $< 900 \text{ N/mm}^2$	suitable	22 m/min	P
Steel $< 1100 \text{ N/mm}^2$	suitable only under restricted conditions	18 m/min	P
GG(G)	suitable only under restricted conditions	30 m/min	K
CuZn	suitable	40 m/min	N

Oil	suitable
wet maximum	suitable

Accessories

HOLEX CleverDrill HSS jobber drillN Ø DC h8 (mm or inch) 7	114031 7
HOLEX CleverDrill jobber drill set HSS No. 114031 in a case Type 1-10	115051 1-10
HOLEX CleverDrill jobber drill set HSS No. 114031 in a case Type 1-10,5	115051 1-10,5
HOLEX CleverDrill jobber drill set HSS No. 114031 in a case Type 1-13	115051 1-13
HOLEX CleverDrill jobber drill set HSS No. 114031 in a case Type 6-10	115051 6-10
HOLEX CleverDrill HSS jobber drill set No. 114031 as a refill set Type 1-10	115056 1-10
HOLEX CleverDrill HSS jobber drill set No. 114031 as a refill set Type 1-10,5	115056 1-10,5
HOLEX CleverDrill HSS jobber drill set No. 114031 as a refill set Type 1-13	115056 1-13
HOLEX CleverDrill HSS jobber drill set No. 114031 as a refill set Type 6-10	115056 6-10