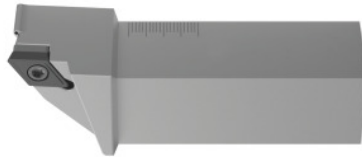


Garant
GARANT Master eco screw-on toolholder short, left-hand, Shank / insert size: 25/11mm

Order data

| | |
|--------------|---------------|
| Order number | 260291 25/11 |
| GTIN | 4067263122463 |
| Item class | 21U |

Description
Version:

Highly efficient cooling directly on the cutting edge and additional flank face cooling.

Note:

Coolant transfer via slot on the underside of the shank in conjunction with GARANT Master eco toolholder No. 319006 – 311936 or No. 317900 for shank length < 125 mm. Optional connection possibility via hose connection (G 1/8 inch) No. 269207 and 269208.

Technical description

| | |
|----------------------------|------------------|
| Shank size | 25 mm |
| Shim | 269007 1 |
| ISO code toolholder | SDJCR/ L 2525H11 |
| Overall length L | 100 mm |
| Shim screw | 269013 7 |
| Series | Master Eco |
| Insert size | 11 mm |
| suitable indexable insert | DC.. 11T3.. |
| Head length L ₁ | 30 mm |

| | |
|---------------------------------|-------------------------------|
| Pack of insert screws | 269023 3 |
| Functional width L ₄ | 32 mm |
| Standard | Works standard |
| Application type | left-hand |
| Through-coolant | yes |
| Setting angle κ | 93 degrees |
| Application | External longitudinal turning |
| Application | External longitudinal turning |
| Type of product | Screw-on toolholder |