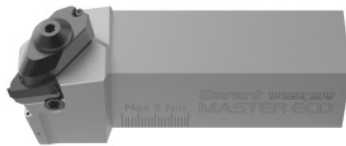


Garant
GARANT Master eco clamping toolholder clamp, right-hand, Shank size / insert size L: 25/16mm

Order data

Order number	272004 25/16
GTIN	4067263122685
Item class	21U

Description
Version:

Highly efficient cooling directly on the cutter and additional flank face cooling.

Supplied with:

With shim 1.5°.

Note:

Coolant transfer via slot on the underside of the shank in conjunction with GARANT Master eco toolholder No. 319006 – 319136 or No. 317900 for shank length < 125 mm. Optional connection possibility via hose connection (G 1/8 inch) No. 269207 and 269208.

Technical description

Functional width L ₄	32 mm
Shim 1.5°	279819 1
Overall length L	100 mm
Series	Master Eco
Shim screw	279824 1
Shank size	25 mm
Clamp, screw, O-ring	279835 3
Head length L ₁	30 mm

Insert size	16 mm
Application type	right-hand
Through-coolant	yes
Type of product	Screw-on toolholder