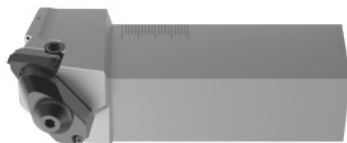


**Garant**
**GARANT Master eco clamping toolholder clamp, left-hand, Shank size / insert size L: 25/16mm**

**Order data**

Order number	272005 25/16
GTIN	4067263122708
Item class	21U

**Description**
**Version:**

Highly efficient cooling directly on the cutter and additional flank face cooling.

**Supplied with:**

**With shim 1.5°.**

**Note:**

Coolant transfer via slot on the underside of the shank in conjunction with GARANT Master eco toolholder No. 319006 – 319136 or No. 317900 for shank length < 125 mm. Optional connection possibility via hose connection (G 1/8 inch) No. 269207 and 269208.

**Technical description**

Functional width L <sub>4</sub>	32 mm
Shim 1.5°	279819 2
Shim screw	279824 1
Shank size	25 mm
Head length L <sub>1</sub>	30 mm
Overall length L	100 mm
Clamp, screw, O-ring	279835 4
Series	Master Eco

Insert size	16 mm
Application type	left-hand
Through-coolant	yes
Type of product	Screw-on toolholder