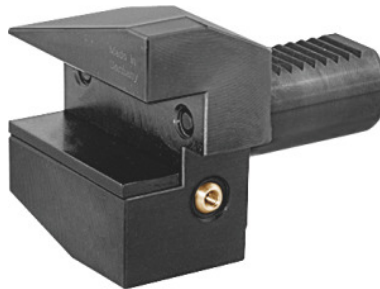



**Toolholder form B3 radial right-hand, short, Shank  $\varnothing$  d1: 30mm**

**Order data**

|              |               |
|--------------|---------------|
| Order number | 319027 30     |
| GTIN         | 4067263201182 |
| Item class   | 32V           |

**Description**
**Version:**

- Case-hardened HRC 58  $\pm$  2.
- All functional faces ground.
- With ball spray nozzles.

**Application:**

Mainly for external machining.

**Standard:**

ISO 10889 / DIN 69880 / VDI 3425, Blatt 2.

**Technical description**

|                                    |        |
|------------------------------------|--------|
| $h_6$                              | 38 mm  |
| $h_1$                              | 20 mm  |
| $b_1$                              | 70 mm  |
| $l_2$                              | 40 mm  |
| Colour code for VDI shanks         | VDI 30 |
| $h_5$                              | 28 mm  |
| Shank $\varnothing$ D <sub>1</sub> | 30 mm  |

|                 |                |
|-----------------|----------------|
| $l_1$           | 22 mm          |
| $b_2$           | 35 mm          |
| $h_2$           | 29 mm          |
| Shape           | B              |
| Type of product | VDI tool arbor |