


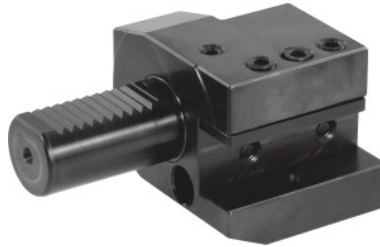

## Toolholder form C2 axial, left-hand, Shank $\varnothing$ d1: 20mm



### Order data

Order number	319117 20
GTIN	4067263237402
Item class	32V

### Description

#### Version:

- Case-hardened HRC 58  $\pm$  2.
- All functional faces ground.
- With ball spray nozzles.

#### Application:

For face cutting in.

#### Standard:

ISO 10889 / DIN 69880 / VDI 3425, Blatt 2.

### Technical description

Shank $\varnothing$ D <sub>1</sub>	20 mm
h <sub>2</sub>	22 mm
h <sub>5</sub>	25 mm
Shank width b <sub>3</sub>	13 mm
h <sub>1</sub>	16 mm
b <sub>2</sub>	27 mm
Colour code for VDI shanks	VDI 20

$h_6$	30 mm
$l_1$	55 mm
$b_1$	52 mm
Shape	C
Type of product	VDI tool arbor