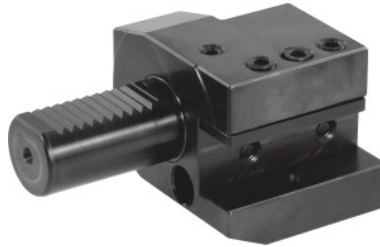


**Toolholder form C2 axial, left-hand, Shank \varnothing d1: 16mm****Order data**

Order number	319117 16
GTIN	4067263224495
Item class	32V

Description**Version:**

- **Case-hardened HRC 58 \pm 2.**
- **All functional faces ground.**
- **With ball spray nozzles.**

Application:

For face cutting in.

Standard:

ISO 10889 / DIN 69880 / VDI 3425, Blatt 2.

Technical description

Colour code for VDI shanks	VDI 16
Shank width b_3	13 mm
Shank \varnothing D_1	16 mm
h_2	17 mm
h_5	20 mm
h_6	22 mm
b_1	43 mm

b_2	24 mm
h_1	12 mm
l_1	44 mm
Shape	C
Type of product	VDI tool arbor