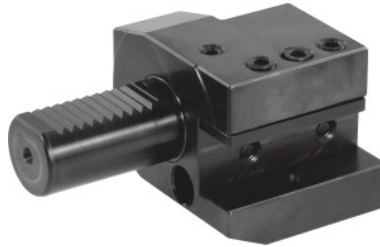


**Toolholder form C2 axial, left-hand, Shank \varnothing d1: 50mm****Order data**

Order number	319117 50
GTIN	4067263237433
Item class	32V

Description**Version:**

- **Case-hardened HRC 58 \pm 2.**
- **All functional faces ground.**
- **With ball spray nozzles.**

Application:

For face cutting in.

Standard:

ISO 10889 / DIN 69880 / VDI 3425, Blatt 2.

Technical description

Shank \varnothing D ₁	50 mm
b ₁	100 mm
Shank width b ₃	26 mm
h ₁	32 mm
Colour code for VDI shanks	VDI 50
h ₂	34 mm
h ₆	60 mm

h_5	50 mm
b_2	50 mm
l_1	100 mm
Shape	C
Type of product	VDI tool arbor