


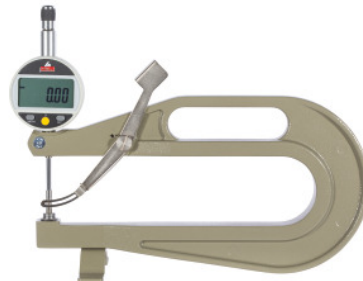

Digital thickness gauge, Measuring range: 0-25mm



Order data

Order number	438192 0-25
GTIN	4031452200461
Item class	46C

Description

Version:

Data transmission via RS 232 or USB with data transmission cable (not included in the scope of supply).

Digital thickness gauge with lift-off lever (gauging force is independent of the user), lightweight frame, painted. Measuring faces hardened and ground.

Supplied with:

1 battery No. 081560 size CR2032.

Technical description

Number of batteries contained	1
Measuring face Ø	10 mm
Article no of the battery / rechargeable battery fitted	081560 CR2032
Throat	200 mm
Power supply	Battery-powered
Scale divisions	0.01 mm
Battery type	Button cell

Measuring range	0 - 25 mm
Interface	USB interface
Interface	Digimatic interface
Measurement variation E MPE (measurement range)	0.02 mm
Standard	Works standard
Type of measurement face	hardened and ground
Measurement technology	digital
Calibration	C6
Type of product	Dial thickness gauge

Services

CalibrationDial thickness gauge maximum measuring range 200	023420 200
DAkkS calibrationDial thickness gauge maximum measuring range 30	023430 30

Accessories

Button cell / special battery Battery type CR2032	081560 CR2032
---	---------------