


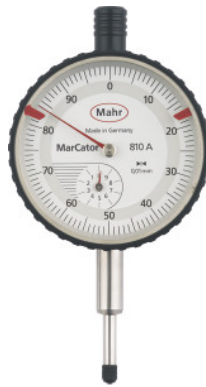

## Dial indicator, Measuring range / Body Ø: 10/58mm



### Order data

Order number	431990 10/58
GTIN	4059192013837
Item class	43A

### Description

#### Version:

Dimensions to DIN EN ISO 463, issue June 2006. Precision dial indicators with metal housing, clamping shank Ø 8 mm h6, hardened and ground. Outer ring of dial face can be rotated to zero the dial. Central pointer for 1/100 mm reading, small pointer on sub-scale for 1 mm reading.

#### Optional extras:

Special contact points No. 434900; 434910; 434915.

### Technical description

Calibration	C1
Gauging force	0.7 - 1.4 N
Clamping shank Ø h6	8 mm
Standard	DIN 878
Graduation	0.01 mm
Measuring range	0 - 10 mm

Body Ø	58 mm
Reading per pointer revolution	1 mm
Measurement variation MPE (measurement range)	15 µm
Measurement technology	mechanical
Packaging	sturdy box
Type of product	dial gauge

### Services

CalibrationDial indicator analogue 0.01 and digital 0.01 / 0.001 maximum measuring span 10 mm	023000 10
DAkkS calibrationDial indicator analogue 0.01 and digital 0.01 / 0.001 maximum measuring span 12,5 mm	023010 12,5