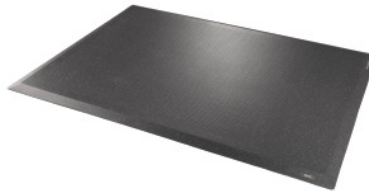


**Garant****Floor mat, dark grey speckled, Width × Length: 100X135cm****Order data**

Order number	964450 100X135
GTIN	4067263476771
Item class	9GM

**Description****Version:**

Industrial workplace mat for medium to heavy-duty requirements. The ergonomic rubber mat is suitable for dry and wet walking and standing workplaces. The mat surface has an optimally coordinated pivot point and very good slip resistance and position stability. Bevelled edges on all sides to avoid the risk of stumbling. Very easy-to-clean surface with light-reflecting properties. The oil-resistant floor mat has a fire protection class Bfl-s1.

Due to the elastic properties of the rubber compound and the special geometry on the rear, the mat has a particularly shock-absorbing and activating effect and protects against unhealthy levels of coldness. Durable mat suitable for multi-shift operation.

Electrically dissipative, surface resistance of less than  $10^7 \Omega$ . The mat is marked with an ESD safety label.

**Supplied with:**

Mat with ESD grounding connection (hole for grounding connection can be freely selected, connection must be self-assembled).

**Technical description**

Thickness	16 mm
Material	Nitrile rubber (NBR)
Weight	20 kg
Width	100 cm

Length	135 cm
Fire protection class	Bfl-s1
Hardness according to Shore A	55
Standing in comfort	Anti-fatiguing
Standing in comfort	Anti-slip
Standing in comfort	Insulation (temperature)
Shock protection	Floor
Material characteristics	oil-resistant
Material characteristics	flame resistant
electrostatic characteristic	EGB/ESD
Colour	dark grey speckled
Type of product	Workplace mat