


HOLEX

**Wheel brush Steel wire 0.50 mm, Brush Ø D1× bore Ø d1 / thread M:
115X22mm**

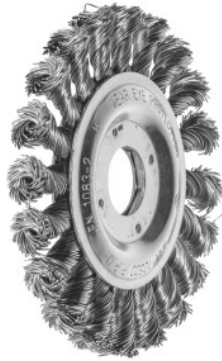

Order data

Order number	571203 115X22
GTIN	4067263906575
Item class	57H

Description

Version:

Straight round brush with smooth wire 0.50 mm, **knotted** and firmly crimped into the steel body. **Very aggressive brushing effect with high wear resistance.**

Application:

For heavy brush work, e.g. descaling, removing rust, removing paint, roughening, cleaning metal parts, also for cleaning formwork boards.

Left knotted, reliably avoids premature unwinding.

Technical description

Bore Ø d ₁	22 mm
Bristle width L ₁	14 mm
maximum speed	12500 min ⁻¹
Brush Ø D ₁	115 mm
Length of brush section H ₁	24 mm

Number of twisted knots	20
Bristle thickness	0.5 mm
Brush material	Steel wire
Type of product	Wheel brush