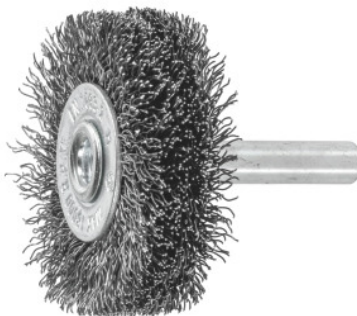


HOLEX**Wheel brush with shank Steel wire 0.30 mm, Brush Ø D1× bristle width L1:
40X10mm****Order data**

Order number	574050 40X10
GTIN	4067263906995
Item class	57H

Description**Version:**

Waved special high quality wire, **shank Ø 6 mm.**

Application:

For portable grinders, on flexible drive machines or drills for brushing surfaces. High speeds improve the brush performance.

For removal of rust and scale, and for cleaning

Technical description

Bristle width L ₁	10 mm
Brush Ø D ₁	40 mm
maximum speed	18000 min ⁻¹
Length of brush section H ₁	9 mm
Shank Ø D _s	6 mm
Bristle thickness	0.3 mm

Brush material	Steel wire
Twisted knotting	waved
Type of product	Wheel brush