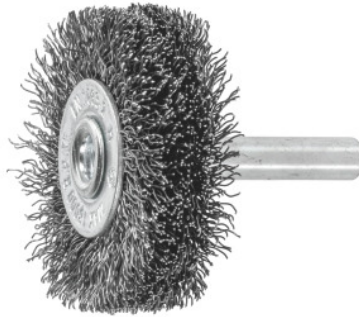


**HOLEX****Wheel brush with shank Steel wire 0.30 mm, Brush Ø D1× bristle width L1:  
50X15mm****Order data**

|              |               |
|--------------|---------------|
| Order number | 574050 50X15  |
| GTIN         | 4067263907008 |
| Item class   | 57H           |

**Description****Version:**

Waved special high quality wire, **shank Ø 6 mm.**

**Application:**

For portable grinders, on flexible drive machines or drills for brushing surfaces. High speeds improve the brush performance.

For removal of rust and scale, and for cleaning

**Technical description**

|  |                         |
|--|-------------------------|
| Bristle width L <sub>1</sub>           | 15 mm                   |
| maximum speed                          | 15000 min <sup>-1</sup> |
| Shank Ø D <sub>s</sub>                 | 6 mm                    |
| Length of brush section H <sub>1</sub> | 12 mm                   |
| Bristle thickness                      | 0.3 mm                  |
| Brush Ø D <sub>1</sub>                 | 50 mm                   |

|                  |             |
|------------------|-------------|
| Brush material   | Steel wire  |
| Twisted knotting | waved       |
| Type of product  | Wheel brush |