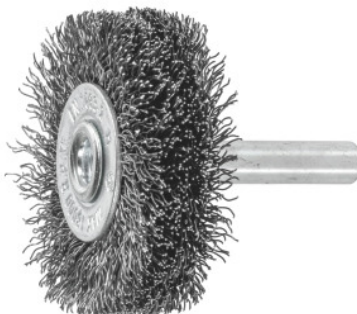


HOLEX**Wheel brush with shank Steel wire 0.30 mm, Brush \varnothing D1 \times bristle width L1: 60X15mm****Order data**

Order number	574050 60X15
GTIN	4067263907015
Item class	57H

Description**Version:**

Waved special high quality wire, **shank \varnothing 6 mm.**

Application:

For portable grinders, on flexible drive machines or drills for brushing surfaces. High speeds improve the brush performance.

For removal of rust and scale, and for cleaning

Technical description

Brush \varnothing D ₁	60 mm
maximum speed	15000 min ⁻¹
Length of brush section H ₁	17 mm
Bristle thickness	0.3 mm
Shank \varnothing D _s	6 mm
Bristle width L ₁	15 mm

Brush material	Steel wire
Twisted knotting	waved
Type of product	Wheel brush