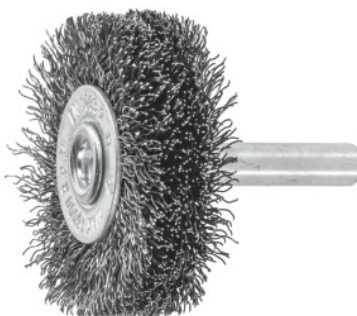


HOLEX**Wheel brush with shank Steel wire 0.20 mm, Brush \varnothing D1 \times bristle width L1: 30X6mm****Order data**

| | |
|--------------|---------------|
| Order number | 574150 30X6 |
| GTIN | 4067263907046 |
| Item class | 57H |

Description**Version:**

Waved special high quality wire, **shank \varnothing 6 mm.**

Application:

For portable grinders, on flexible drive machines or drills for brushing surfaces. High speeds improve the brush performance.

For removal of rust and scale, and for cleaning

Technical description

| | |
|--|-------------------------|
| Bristle thickness | 0.2 mm |
| Length of brush section H ₁ | 6 mm |
| Shank \varnothing D _s | 6 mm |
| Brush \varnothing D ₁ | 30 mm |
| Bristle width L ₁ | 6 mm |
| maximum speed | 20000 min ⁻¹ |

| | |
|------------------|-------------|
| Brush material | Steel wire |
| Twisted knotting | waved |
| Type of product | Wheel brush |