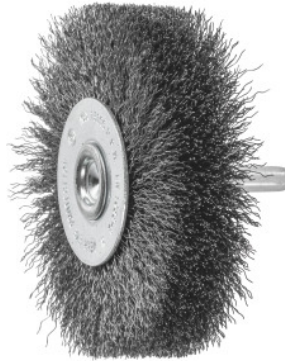


HOLEX**Wheel brush with shank Steel wire 0.20 mm, Brush Ø D1× bristle width L1:
80X18mm****Order data**

Order number	574150 80X18
GTIN	4067263907091
Item class	57H

Description**Version:**

Waved special high quality wire, **shank Ø 6 mm.**

Application:

For portable grinders, on flexible drive machines or drills for brushing surfaces. High speeds improve the brush performance.

For removal of rust and scale, and for cleaning

Technical description

Brush Ø D ₁	80 mm
maximum speed	15000 min ⁻¹
Shank Ø D _s	6 mm
Bristle width L ₁	13 mm
Length of brush section H ₁	20 mm
Brush material	Steel wire

Twisted knotting	waved
Type of product	Wheel brush