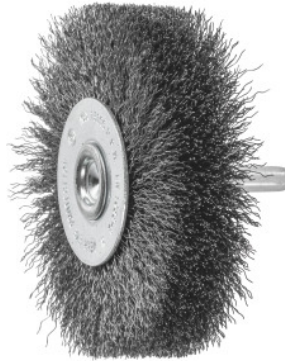


HOLEX**Wheel brush with shank Steel wire 0.20 mm, Brush Ø D1× bristle width L1:
70X16mm****Order data**

Order number	574150 70X16
GTIN	4067263907084
Item class	57H

Description**Version:**

Waved special high quality wire, **shank Ø 6 mm.**

Application:

For portable grinders, on flexible drive machines or drills for brushing surfaces. High speeds improve the brush performance.

For removal of rust and scale, and for cleaning

Technical description

Length of brush section H ₁	19 mm
Shank Ø D _s	6 mm
maximum speed	15000 min ⁻¹
Brush Ø D ₁	70 mm
Bristle width L ₁	14 mm
Brush material	Steel wire

Twisted knotting	waved
Type of product	Wheel brush