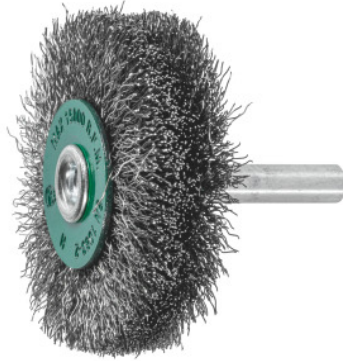


**Wheel brush with shank Stainless steel wire 0.20 mm, Brush  $\varnothing$  D1 $\times$  bristle width L1: 30X6mm****Order data**

Order number	574253 30X6
GTIN	4067263934745
Item class	57H

**Description****Version:**

Waved special high quality wire, **shank  $\varnothing$  6 mm.**

**Application:**

For portable grinders, on flexible drive machines or drills for brushing surfaces. High speeds improve the brush performance.

For removal of rust and scale, and for cleaning

**Technical description**

Brush $\varnothing$ D <sub>1</sub>	30 mm
Bristle thickness	0.2 mm
Bristle width L <sub>1</sub>	6 mm
maximum speed	20000 min <sup>-1</sup>
Length of brush section H <sub>1</sub>	6 mm
Shank $\varnothing$ D <sub>s</sub>	6 mm

## Data sheet

Brush material	Stainless steel wire
Twisted knotting	waved
Type of product	Wheel brush