


**HOLEX**

**Wheel brush with shank Stainless steel wire 0.30 mm, Brush  $\varnothing$  D1× bristle width L1: 70X10mm**

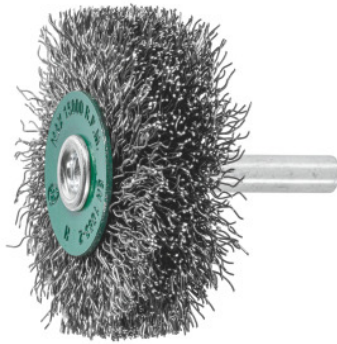

## Order data

Order number	574225 70X10
GTIN	4067263934714
Item class	57H

## Description

### Version:

Waved special high quality wire, **shank  $\varnothing$  6 mm.**

### Application:

For portable grinders, on flexible drive machines or drills for brushing surfaces. High speeds improve the brush performance.

For removal of rust and scale, and for cleaning

## Technical description

Length of brush section H <sub>1</sub>	19 mm
Bristle thickness	0.3 mm
Brush $\varnothing$ D <sub>1</sub>	70 mm
Shank $\varnothing$ D <sub>s</sub>	6 mm
maximum speed	15000 min <sup>-1</sup>
Bristle width L <sub>1</sub>	10 mm

Brush material	Stainless steel wire
Twisted knotting	waved
Type of product	Wheel brush