


HOLEX

Wheel brush with shank Stainless steel wire 0.30 mm, Brush \varnothing D₁ × bristle width L₁: 80X18mm

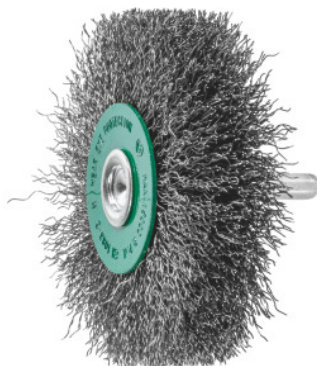

Order data

Order number	574225 80X18
GTIN	4067263934738
Item class	57H

Description

Version:

Waved special high quality wire, **shank \varnothing 6 mm.**

Application:

For portable grinders, on flexible drive machines or drills for brushing surfaces. High speeds improve the brush performance.

For removal of rust and scale, and for cleaning

Technical description

Bristle width L ₁	18 mm
Bristle thickness	0.3 mm
Brush width	18 mm
Brush \varnothing D ₁	80 mm
Shank \varnothing D _s	6 mm
maximum speed	15000 min ⁻¹

Length of brush section H ₁	20 mm
Brush material	Stainless steel wire
Twisted knotting	waved
Type of product	Wheel brush