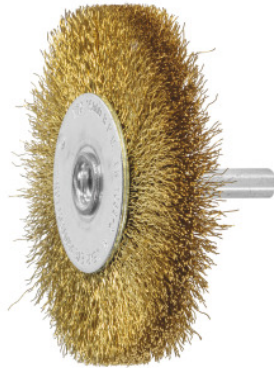


HOLEX**Wheel brush with shank Brass wire 0.20 mm., Brush \varnothing D1 \times bristle width L1: 60X15mm****Order data**

Order number	574360 60X15
GTIN	4067263934820
Item class	57H

Description**Version:**

Waved special high quality wire, **shank \varnothing 6 mm.**

Application:

For portable grinders, on flexible drive machines or drills for brushing surfaces. High speeds improve the brush performance.

For heavy-duty deburring and brushing of non-ferrous metals

Technical description

Brush \varnothing D ₁	60 mm
Bristle width L ₁	15 mm
maximum speed	15000 min ⁻¹
Shank \varnothing D _s	6 mm
Bristle thickness	0.2 mm
Length of brush section H ₁	17 mm

Brush material	Brass wire
Twisted knotting	waved
Type of product	Wheel brush