


**Garant**

**Vario plus eco blade carrier, convex for face grooving, right-hand, Ø range for groove D1 / D2: 41/53mm**

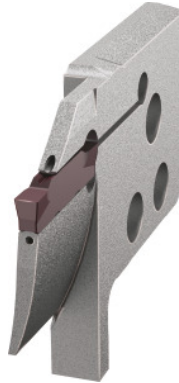

## Order data

Order number	274512 41/53
GTIN	4067263934981
Item class	21U

## Description

**Version:**

Optimised system stability thanks to multiple screw clamping and form fit.

**Suitable for:**

Toolholder No. 274500 – 274503, 274530, 274531.

**Attention:**

Without clamping screws (these are supplied with the toolholders).

**Note:**

$D_1$  = minimum Ø for the first first groove /  $D_2$  = minimum Ø for the second groove.

## Technical description

minimum 1st groove Ø $D_1$	41 mm
maximum cutting depth $t_{max}$	16 mm
maximum 1st groove Ø $D_2$	53 mm
Series	Eco

## Data sheet

suitable indexable insert	No. 273656 – 273749
Application type	right-hand
Through-coolant	yes
Groove width w	2 mm
Type of product	Cartridges