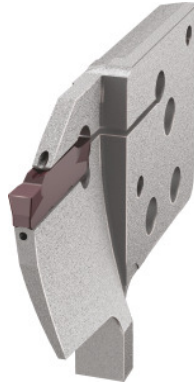


**Garant**

**Vario plus Eco blade carrier, convex for face grooving, left-hand, Ø range for groove D1 / D2: 138/190mm**


**Order data**

Order number	274513 138/190
GTIN	4067263950424
Item class	21U

**Description**
**Version:**

Optimised system stability thanks to multiple screw clamping and form fit.

**Suitable for:**

Toolholder No. 274500 – 274503, 274530, 274531.

**Attention:**

Without clamping screws (these are supplied with the toolholders).

**Note:**

D<sub>1</sub> = minimum Ø for the first first groove / D<sub>2</sub> = minimum Ø for the second groove.

**Technical description**

Series	Eco
maximum 1st groove Ø D <sub>2</sub>	190 mm
suitable indexable insert	No. 273656 – 273749
minimum 1st groove Ø D <sub>1</sub>	138 mm

maximum cutting depth $t_{\max}$	18 mm
Application type	left-hand
Through-coolant	yes
Groove width $w$	2 mm
Type of product	Cartridges