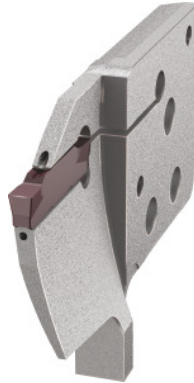


**Garant**

**Vario plus Eco blade carrier, convex for face grooving, left-hand, Ø range for groove D1 / D2: 43/60mm**


**Order data**

Order number	274517 43/60
GTIN	4067263935254
Item class	21U

**Description**
**Version:**

Optimised system stability thanks to multiple screw clamping and form fit.

**Suitable for:**

Toolholder No. 274500 – 274503, 274530, 274531.

**Attention:**

Without clamping screws (these are supplied with the toolholders).

**Note:**

$D_1$  = minimum Ø for the first first groove /  $D_2$  = minimum Ø for the second groove.

**Technical description**

suitable indexable insert	No. 273656 – 273749
maximum cutting depth $t_{max}$	18 mm
Series	Eco
maximum 1st groove Ø $D_2$	60 mm

minimum 1st groove $\varnothing D_1$	43 mm
Application type	left-hand
Through-coolant	yes
Groove width w	3 mm
Type of product	Cartridges