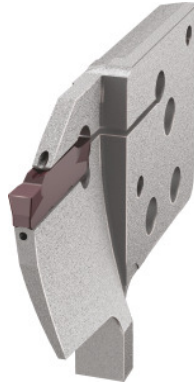


Garant

Vario plus Eco blade carrier, convex for face grooving, left-hand, Ø range for groove D1 / D2: 140/230mm

**Order data**

Order number	274517 140/230
GTIN	4067263950806
Item class	21U

Description**Version:**

Optimised system stability thanks to multiple screw clamping and form fit.

Suitable for:

Toolholder No. 274500 – 274503, 274530, 274531.

Attention:

Without clamping screws (these are supplied with the toolholders).

Note:

D₁ = minimum Ø for the first first groove / D₂ = minimum Ø for the second groove.

Technical description

maximum 1st groove Ø D ₂	230 mm
suitable indexable insert	No. 273656 – 273749
maximum cutting depth t _{max}	21 mm
minimum 1st groove Ø D ₁	140 mm

Series	Eco
Application type	left-hand
Through-coolant	yes
Groove width w	3 mm
Type of product	Cartridges