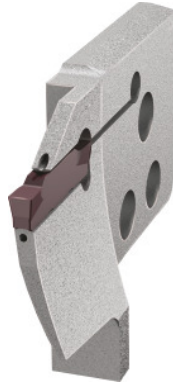


Garant**Vario plus eco blade carrier, concave for face grooving, right-hand, Ø range for groove D1 / D2: 26/39mm**

Order data

Order number	274518 26/39
GTIN	4067263950813
Item class	21U

Description

Version:

Optimised system stability thanks to multiple screw clamping and form fit.

Suitable for:

Toolholder No. 274500 – 274503, 274530, 274531.

Attention:

Without clamping screws (these are supplied with the toolholders).

Note:

D₁ = minimum Ø for the first groove / D₂ = minimum Ø for the second groove.

Technical description

maximum 1st groove Ø D ₂	39 mm
minimum 1st groove Ø D ₁	26 mm
suitable indexable insert	No. 273656 – 273749
Series	Eco

Data sheet

maximum cutting depth t_{\max}	18 mm
Application type	right-hand
Through-coolant	yes
Groove width w	3 mm
Type of product	Cartridges