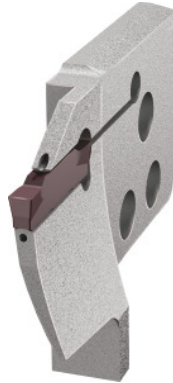


Garant**Vario plus eco blade carrier, concave for face grooving, right-hand, Ø range for groove D1 / D2: 33/50mm****Order data**

Order number	274518 33/50
GTIN	4067263950820
Item class	21U

Description**Version:**

Optimised system stability thanks to multiple screw clamping and form fit.

Suitable for:

Toolholder No. 274500 – 274503, 274530, 274531.

Attention:

Without clamping screws (these are supplied with the toolholders).

Note:

D_1 = minimum Ø for the first groove / D_2 = minimum Ø for the second groove.

Technical description

minimum 1st groove Ø D_1	33 mm
maximum cutting depth t_{max}	18 mm
maximum 1st groove Ø D_2	50 mm
suitable indexable insert	No. 273656 – 273749

Data sheet

Series	Eco
Application type	right-hand
Through-coolant	yes
Groove width w	3 mm
Type of product	Cartridges