


Garant

Vario plus eco blade carrier, concave for face grooving, right-hand, Ø range for groove D1 / D2: 53/76mm

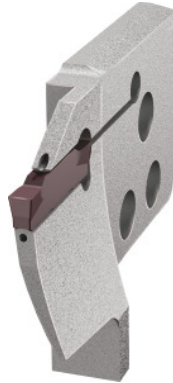

Order data

Order number	274518 53/76
GTIN	4067263950844
Item class	21U

Description

Version:

Optimised system stability thanks to multiple screw clamping and form fit.

Suitable for:

Toolholder No. 274500 – 274503, 274530, 274531.

Attention:

Without clamping screws (these are supplied with the toolholders).

Note:

D_1 = minimum Ø for the first first groove / D_2 = minimum Ø for the second groove.

Technical description

minimum 1st groove Ø D_1	53 mm
maximum cutting depth t_{max}	18 mm
Series	Eco
suitable indexable insert	No. 273656 – 273749

Data sheet

maximum 1st groove $\varnothing D_2$	76 mm
Application type	right-hand
Through-coolant	yes
Groove width w	3 mm
Type of product	Cartridges