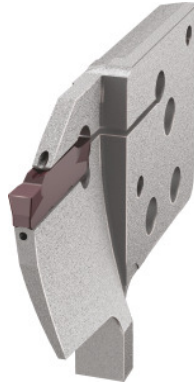


Garant

Vario plus eco blade carrier, convex for face grooving, left-hand, Ø range for groove D1 / D2: 150/250mm


Order data

Order number	274521 150/250
GTIN	4067263962236
Item class	21U

Description
Version:

Optimised system stability thanks to multiple screw clamping and form fit.

Suitable for:

Toolholder No. 274500 – 274503, 274530, 274531.

Attention:

Without clamping screws (these are supplied with the toolholders).

Note:

D_1 = minimum Ø for the first first groove / D_2 = minimum Ø for the second groove.

Technical description

suitable indexable insert	No. 273656 – 273749
maximum cutting depth t_{max}	28 mm
maximum 1st groove Ø D_2	250 mm
Series	Eco

minimum 1st groove $\varnothing D_1$	150 mm
Application type	left-hand
Through-coolant	yes
Groove width w	4 mm
Type of product	Cartridges