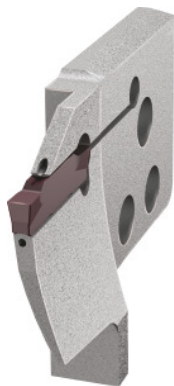


Garant**Vario plus eco blade carrier, concave for face grooving, right-hand, Ø range for groove D1 / D2: 150/250mm****Order data**

Order number	274522 150/250
GTIN	4067263962359
Item class	21U

Description**Version:**

Optimised system stability thanks to multiple screw clamping and form fit.

Suitable for:

Toolholder No. 274500 – 274503, 274530, 274531.

Attention:

Without clamping screws (these are supplied with the toolholders).

Note:

D_1 = minimum Ø for the first first groove / D_2 = minimum Ø for the second groove.

Technical description

maximum cutting depth t_{max}	28 mm
minimum 1st groove Ø D_1	150 mm
Series	Eco
maximum 1st groove Ø D_2	250 mm

suitable indexable insert	No. 273656 – 273749
Application type	right-hand
Through-coolant	yes
Groove width w	4 mm
Type of product	Cartridges